

Technical data sheet

Flat angle cover, trunking type WDK 30030

Item number: 6158641



Flat angle hood for changing the direction of the WDK trunking.



PVC

 Polyvinylchloride

Master data	
Item number	6158641
Description 1	Flat angle cover
Manufacturer	OBO
Dimension	30x30mm
Colour	Stone grey; RAL 7030
Material	Polyvinylchloride
Smallest sales unit	4
Unit of quantity	Piece
Weight	1.37 kg
Weight unit	kg/100 pc.


Technical data sheet

Flat angle cover, trunking type WDK 30030

Item number: 6158641



Dimensions

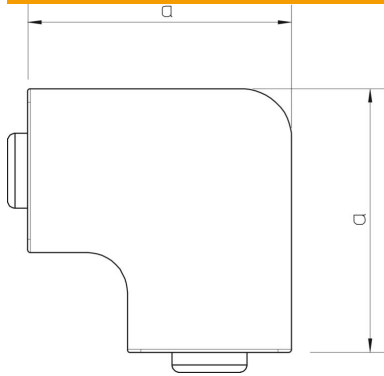

Length	53 mm
Width	30 mm
Height	30 mm
Dimension a	53 mm
Dimension H	30 mm

Technical data

Version for	Hood fitting
Fastening type	Lockable
Maintain electrical functions	no
for duct dimension	30 x 30
Halogen-free	no
Trunking depth	30 mm
Protection rating	IP30
Protective film	no
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C
Angle range, max.	90 mm
Angle range, min.	90 mm