

Technical data sheet

Flat angle cover, trunking type WDK 30045

Item number: 6161286



Flat angle hood for changing the direction of the WDK trunking.



PVC Polyvinylchloride

Master data

Item number	6161286
Type	WDK HF30045CW
Description 1	Flat angle cover
Manufacturer	OBO
Dimension	30x45mm
Colour	Cream; RAL 9001
Material	Polyvinylchloride
Smallest sales unit	4
Unit of quantity	Piece
Weight	1.922 kg
Weight unit	kg/100 pc.


Technical data sheet

Flat angle cover, trunking type WDK 30045

Item number: 6161286



Dimensions

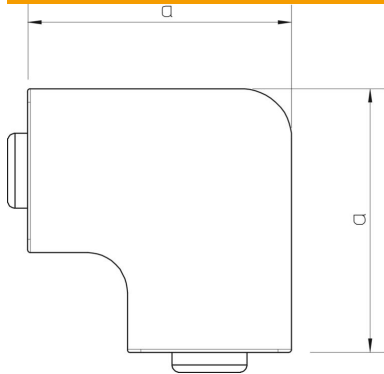

Length	68 mm
Width	45 mm
Height	30 mm
Dimension a	68 mm
Dimension H	45 mm

Technical data

Version for	Hood fitting
Fastening type	Lockable
Maintain electrical functions	no
for duct dimension	30 x 45
Halogen-free	no
Trunking depth	30 mm
Protection rating	IP30
Protective film	no
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C
Angle range, max.	90 mm
Angle range, min.	90 mm