

Technical data sheet

Flat angle cover, trunking type WDK 40040

Item number: 6192831



Flat angle cover for changing the direction of the WDK trunking.



Master data		
Item number	6192831	
Description 1	Flat angle cover	
Manufacturer	OBO	
Dimension	40x40mm	
Colour	Pure white; RAL 9010	
Material	Polyvinylchloride	
Smallest sales unit	4	
Unit of quantity	Piece	
Weight	2.534 kg	
Weight unit	kg/100 pc.	
CO Footprint (GWP) Cradle-to-Gate	8,1102 kg COe / 1 Piece	


Technical data sheet

Flat angle cover, trunking type WDK 40040

Item number: 6192831



Dimensions

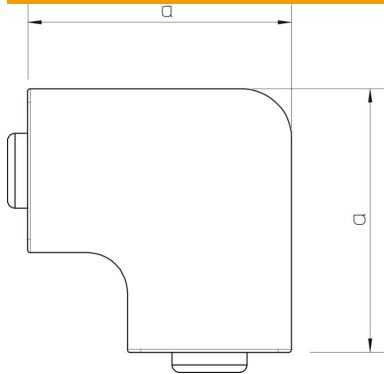

Length	63 mm
Width	40 mm
Height	40 mm
Dimension a	63 mm
Dimension H	40 mm

Technical data

Version for	Hood fitting
Fastening type	Lockable
Maintain electrical functions	no
for duct dimension	40 x 40
Halogen-free	no
Trunking depth	40 mm
Protection rating	IP30
Protective film	no
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C
Angle range, max.	90 mm
Angle range, min.	90 mm