

Technical data sheet

Flat angle cover, trunking type WDK 60060

Item number: 6192912



Flat angle hood for changing the direction of the WDK trunking.



PVC

 Polyvinylchloride

Master data	
Item number	6192912
Description 1	Flat angle cover
Manufacturer	OBO
Dimension	60x60mm
Colour	Pure white; RAL 9010
Material	Polyvinylchloride
Smallest sales unit	2
Unit of quantity	Piece
Weight	7.846 kg
Weight unit	kg/100 pc.
CO Footprint (GWP) Cradle-to-Gate	0,2096 kg COe / 1 Piece


Technical data sheet

Flat angle cover, trunking type WDK 60060

Item number: 6192912



Dimensions

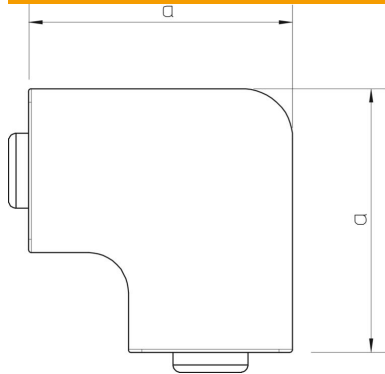

Length	101 mm
Width	60 mm
Height	60 mm
Dimension a	101 mm
Dimension H	60 mm

Technical data

Version for	Hood fitting
Fastening type	Lockable
Maintain electrical functions	no
for duct dimension	60 x 60
Halogen-free	no
Trunking depth	60 mm
Protection rating	IP30
Protective film	no
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C
Angle range, max.	90 mm
Angle range, min.	90 mm