


Technical data sheet

Flat angle cover, trunking type WDK 60110

Item number: 6192939



Flat angle hood for changing the direction of the WDK trunking.

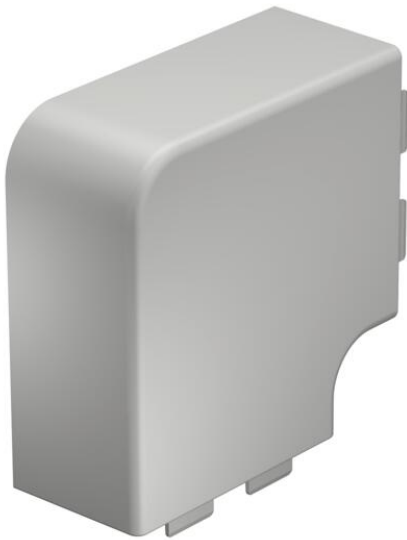

PVC

 Polyvinylchloride

Master data		
Item number	6192939	
Type	WDK HF60110RW	
Description 1	Flat angle cover	
Manufacturer	OBO	
Dimension	60x110mm	
Colour	Pure white; RAL 9010	
Material	Polyvinylchloride	
Smallest sales unit	2	
Unit of quantity	Piece	
Weight	14.273 kg	
Weight unit	kg/100 pc.	
CO2 Footprint (GWP) Cradle-to-Gate	0,3376 kg CO2e / 1 Piece	


Technical data sheet

Flat angle cover, trunking type WDK 60110

Item number: 6192939



Dimensions

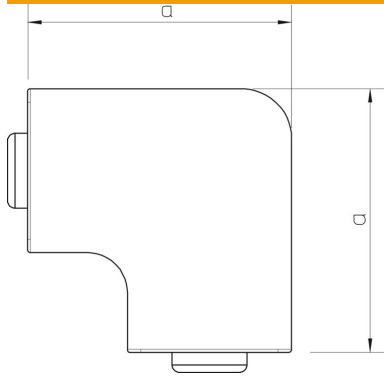

Length	149 mm
Width	110 mm
Height	60 mm
Dimension a	149 mm
Dimension H	110 mm

Technical data

Version for	Hood fitting
Fastening type	Lockable
Maintain electrical functions	no
for duct dimension	60 x 110
Halogen-free	no
Trunking depth	60 mm
Protection rating	IP30
Protective film	no
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C
Angle range, max.	90 mm
Angle range, min.	90 mm