

Technical data sheet

Flat angle cover, trunking type WDK 60150

Item number: 6183441



Flat angle hood for changing the direction of the WDK trunking.



PVC Polyvinylchloride

Master data

Item number	6183441
Type	WDK HF60150LGR
Description 1	Flat angle cover
Manufacturer	OBO
Dimension	60x150mm
Colour	Light grey; RAL 7035
Material	Polyvinylchloride
Smallest sales unit	2
Unit of quantity	Piece
Weight	19.91 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,4805 kg CO2e / 1 Piece


Technical data sheet

Flat angle cover, trunking type WDK 60150

Item number: 6183441



Dimensions

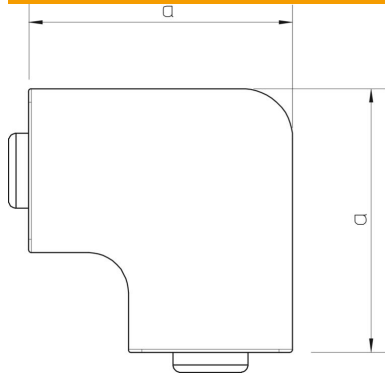

Length	190 mm
Width	155 mm
Height	60 mm
Dimension a	190 mm
Dimension H	150 mm

Technical data

Version for	Hood fitting
Fastening type	Lockable
Maintain electrical functions	no
for duct dimension	60 x 150
Halogen-free	no
Trunking depth	60 mm
Protection rating	IP30
Protective film	no
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C
Angle range, max.	90 mm
Angle range, min.	90 mm