

Technical data sheet

Flat angle cover, trunking type WDK 60170

Item number: 6022375



Flat angle hood for changing the direction of the WDK trunking.



PVC

 Polyvinylchloride

Master data	
Item number	6022375
Description 1	Flat angle cover
Manufacturer	OBO
Dimension	60x170mm
Colour	Stone grey; RAL 7030
Material	Polyvinylchloride
Smallest sales unit	2
Unit of quantity	Piece
Weight	22.774 kg
Weight unit	kg/100 pc.


Technical data sheet

Flat angle cover, trunking type WDK 60170

Item number: 6022375



Dimensions

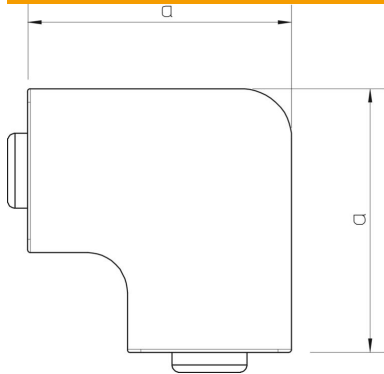

Length	211 mm
Width	170 mm
Height	60 mm
Dimension a	211 mm
Dimension H	170 mm

Technical data

Version for	Hood fitting
Fastening type	Lockable
Maintain electrical functions	no
for duct dimension	60 x 170
Halogen-free	no
Trunking depth	60 mm
Protection rating	IP30
Protective film	no
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C
Angle range, max.	90 mm
Angle range, min.	90 mm