


Technical data sheet

Internal corner cover, trunking type WDK 30045

Item number: 6160085



Internal corner cover for changing the direction of the WDK trunking.

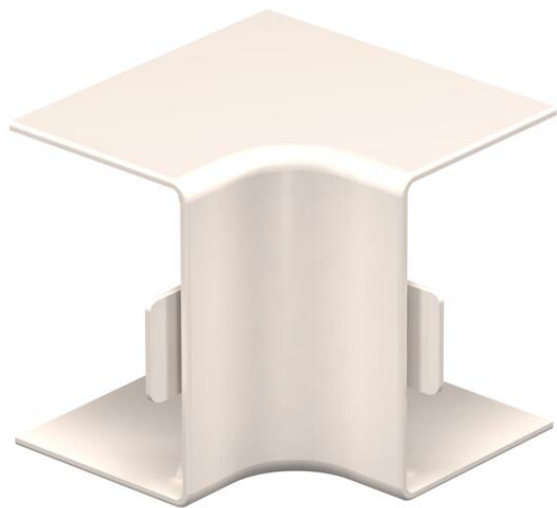

PVC Polyvinylchloride

Master data	
Item number	6160085
Type	WDK HI30045CW
Description 1	Internal corner cover
Manufacturer	OBO
Dimension	30x45mm
Colour	Cream; RAL 9001
Material	Polyvinylchloride
Smallest sales unit	4
Unit of quantity	Piece
Weight	1.295 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0817 kg CO2e / 1 Piece


Technical data sheet

Internal corner cover, trunking type WDK 30045

Item number: 6160085



Dimensions

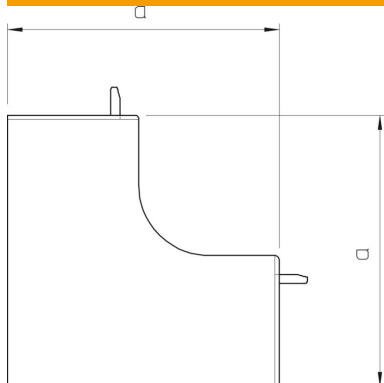

Length	52 mm
Width	45 mm
Height	30 mm
Dimension a	52 mm

Technical data

Version for	Hood fitting
Fastening type	Lockable
Maintain electrical functions	no
Halogen-free	no
Protection rating	IP30
Protective film	no
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C
Angle range, max.	90 mm
Angle range, min.	90 mm