


Technical data sheet

T and intersection cover, for trunking type WDK 40110

Item number: 6162029

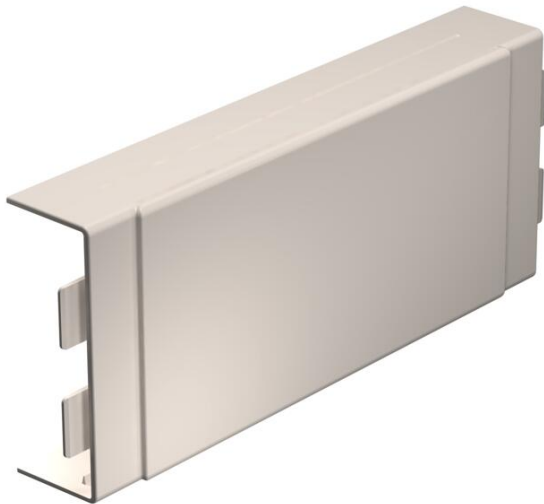

T and intersection cover for changing the direction of the WDK trunking. The fitting is preperforated at the side for the connection of different trunking cross-sections.




PVC Polyvinylchloride

Master data

Item number	6162029
Type	WDK HK40110CW
Description 1	T- and crosspiece cover
Manufacturer	OBO
Dimension	40x110mm
Colour	Cream; RAL 9001
Material	Polyvinylchloride
Smallest sales unit	2
Unit of quantity	Piece
Weight	18.882 kg
Weight unit	kg/100 pc.

Dimensions

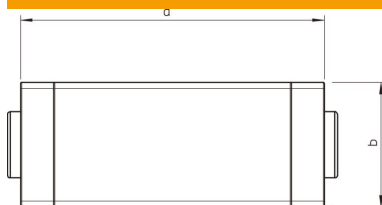

Length	272 mm
Width	110 mm
Height	40 mm
Dimension a	272 mm
Dimension b	112 mm
Dimension H	110 mm

Technical data sheet

T and intersection cover, for trunking type WDK 40110

Item number: 6162029



Technical data

Version for	Hood fitting
Fastening type	Lockable
Maintain electrical functions	no
for duct dimension	40 x 110
Trunking depth	40 mm
Protection rating	IP30
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C