


Technical data sheet

Joint cover, trunking type WDK 10020

Item number: 6154026



Joint cover for smooth connection of trunking segments.

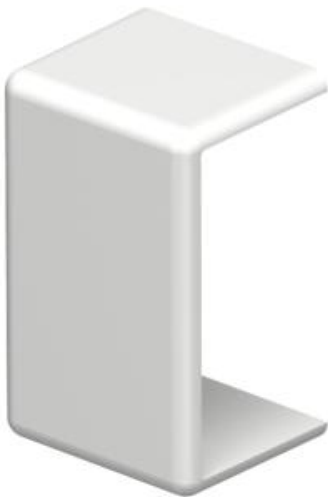

PVC

 Polyvinylchloride

Master data		
Item number	6154026	
Description 1	Joint cover	
Manufacturer	OBO	
Dimension	10x20mm	
Colour	Pure white; RAL 9010	
Material	Polyvinylchloride	
Smallest sales unit	10	
Unit of quantity	Piece	
Weight	0.09 kg	
Weight unit	kg/100 pc.	


Technical data sheet

Joint cover, trunking type WDK 10020

Item number: 6154026



Dimensions

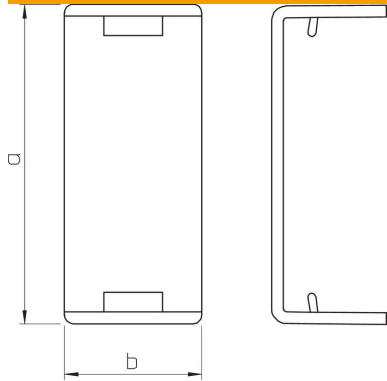

Length	14 mm
Width	22 mm
Height	10 mm
Dimension a	22 mm
Dimension b	14 mm
Dimension H	20 mm

Technical data

Version for	Trunking cut cover
Fastening type	Lockable
Shape	Symmetrical
for duct dimension	10x20
Halogen-free	no
Trunking depth	10 mm
Cover width	14 mm
Protection rating	IP30
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C