

Technical data sheet

Joint cover, for trunking, type WDK 13025

Item number: 6193498



Joint cover for perfect connection of the WDK trunking segments, type 13025. Incl. coupling for the raised trunking floor.




Polycarbonate/Acrylnitrile-butadiene-styrene

Master data

Item number	6193498
Type	WDK HS13025RW
Description 1	Joint cover
Description 2	with coupling for raised floor
Manufacturer	OBO
Dimension	15x27x50mm
Colour	Pure white; RAL 9010
Material	Polycarbonate/Acrylnitrile-butadiene-styrene
Smallest sales unit	20
Unit of quantity	Piece
Weight	0.556 kg
Weight unit	kg/100 pc.

Dimensions

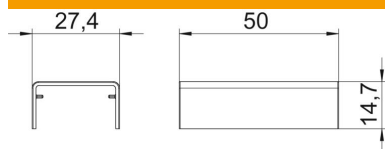

Length	50 mm
Width	27.4 mm
Height	14.7 mm

Technical data sheet

Joint cover, for trunking, type WDK 13025

Item number: 6193498



Technical data

Version for	Trunking cut cover
Fastening type	Lockable
Shape	Symmetrical
Halogen-free	no
Protection rating	IP30
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C