

Technical data sheet

Joint cover, for trunking, type WDK 15030

Item number: 6152031



Joint cover for smooth connection of trunking segments.



Master data		
Item number	6152031	
Type	WDK HS15030CW	
Description 1	Joint cover	
Manufacturer	OBO	
Dimension	15x30mm	
Colour	Cream; RAL 9001	
Material	Polyvinylchloride	
Smallest sales unit	10	
Unit of quantity	Piece	
Weight	0.136 kg	
Weight unit	kg/100 pc.	
CO2 Footprint (GWP) Cradle-to-Gate	0,0133 kg CO2e / 1 Piece	


Technical data sheet

Joint cover, for trunking, type WDK 15030

Item number: 6152031



Dimensions

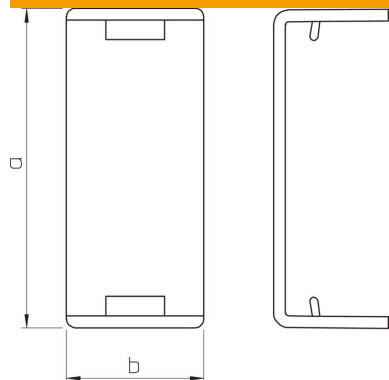

Length	14 mm
Width	32 mm
Height	18.5 mm
Dimension a	32 mm
Dimension b	14 mm
Dimension H	30 mm

Technical data

Version for	Trunking cut cover
Fastening type	Lockable
Shape	Symmetrical
Halogen-free	no
Trunking depth	15 mm
Cover width	14 mm
Protection rating	IP30
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C