

Technical data sheet

Joint cover, for trunking, type WDK 15030

Item number: 6158838



Joint cover for smooth connection of trunking segments.



PVC Polyvinylchloride

Master data

Item number	6158838
Description 1	Joint cover
Manufacturer	OBO
Dimension	15x30mm
Colour	Stone grey; RAL 7030
Material	Polyvinylchloride
Smallest sales unit	10
Unit of quantity	Piece
Weight	0.136 kg
Weight unit	kg/100 pc.


Technical data sheet

Joint cover, for trunking, type WDK 15030

Item number: 6158838



Dimensions

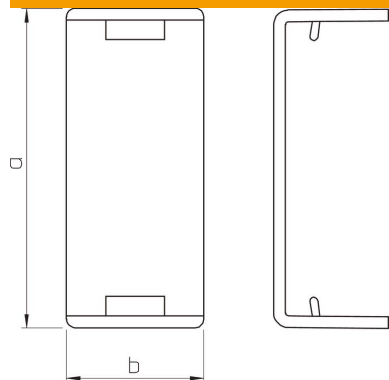

Length	14 mm
Width	32 mm
Height	18.5 mm
Dimension a	32 mm
Dimension b	14 mm
Dimension H	30 mm

Technical data

Version for	Trunking cut cover
Fastening type	Lockable
Shape	Symmetrical
Halogen-free	no
Trunking depth	15 mm
Cover width	14 mm
Protection rating	IP30
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C