

Technical data sheet

Joint cover, for trunking, type WDK 15040

Item number: 6152058



Joint cover for smooth connection of trunking segments.



PVC

Polyvinylchloride

Master data	
Item number	6152058
Description 1	Joint cover
Manufacturer	OBO
Dimension	15x40mm
Colour	Cream; RAL 9001
Material	Polyvinylchloride
Smallest sales unit	20
Unit of quantity	Piece
Weight	0.19 kg
Weight unit	kg/100 pc.


Technical data sheet

Joint cover, for trunking, type WDK 15040

Item number: 6152058



Dimensions

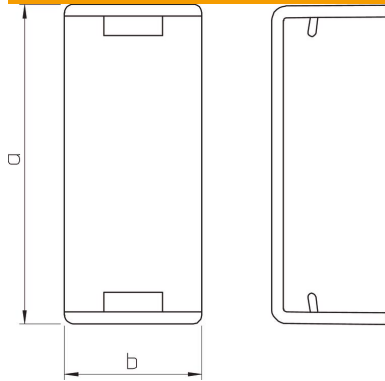

Length	14 mm
Width	42 mm
Height	15 mm
Dimension a	42 mm
Dimension b	14 mm
Dimension H	40 mm

Technical data

Version for	Trunking cut cover
Fastening type	Lockable
Shape	Symmetrical
Halogen-free	no
Trunking depth	15 mm
Cover width	14 mm
Protection rating	IP30
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C