


Technical data sheet

Joint cover, for trunking, type WDK 15040

Item number: 6158846



Joint cover for smooth connection of trunking segments.

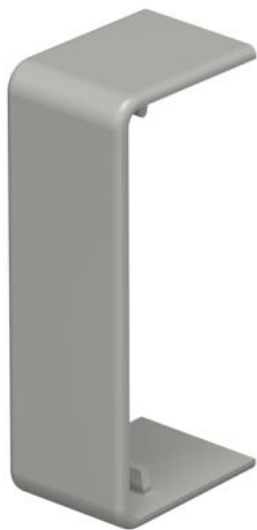

PVC Polyvinylchloride

Master data		
Item number	6158846	
Description 1	Joint cover	
Manufacturer	OBO	
Dimension	15x40mm	
Colour	Stone grey; RAL 7030	
Material	Polyvinylchloride	
Smallest sales unit	10	
Unit of quantity	Piece	
Weight	0.19 kg	
Weight unit	kg/100 pc.	


Technical data sheet

Joint cover, for trunking, type WDK 15040

Item number: 6158846



Dimensions

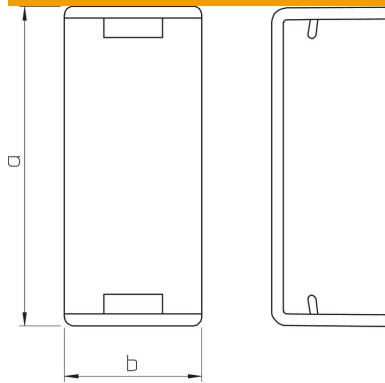

Length	14 mm
Width	42 mm
Height	15 mm
Dimension a	42 mm
Dimension b	14 mm
Dimension H	40 mm

Technical data

Version for	Trunking cut cover
Fastening type	Lockable
Shape	Symmetrical
Halogen-free	no
Trunking depth	15 mm
Cover width	14 mm
Protection rating	IP30
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C