

Technical data sheet

Joint cover, for trunking, type WDK 60090

Item number: 6193592



Joint cover for hiding cut edges and for smooth connection of trunking segments.



PVC Polyvinylchloride

Master data

Item number	6193592
Type	WDK HS60090CW
Description 1	Joint cover
Description 2	for WDK 60090
Manufacturer	OBO
Dimension	62x93x18mm
Colour	Cream; RAL 9001
Material	Polyvinylchloride
Smallest sales unit	20
Unit of quantity	Piece
Weight	1.008 kg
Weight unit	kg/100 pc.


Technical data sheet

Joint cover, for trunking, type WDK 60090

Item number: 6193592



Dimensions

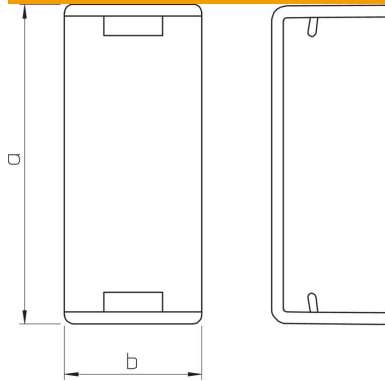

Length	18 mm
Width	94 mm
Height	62 mm
Dimension a	94 mm
Dimension b	18 mm

Technical data

Version for	Trunking cut cover
Fastening type	Lockable
Shape	Symmetrical
Halogen-free	no
Protection rating	IP30
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C