

Technical data sheet

Joint cover, for trunking, type WDK 60110

Item number: 6193598



Joint cover for hiding cut edges and for smooth connection of trunking segments.



PVC Polyvinylchloride

Master data

Item number	6193598
Type	WDK HS60110CW
Description 1	Joint cover
Description 2	for WDK 60110
Manufacturer	OBO
Dimension	62x113x18mm
Colour	Cream; RAL 9001
Material	Polyvinylchloride
Smallest sales unit	20
Unit of quantity	Piece
Weight	1.142 kg
Weight unit	kg/100 pc.


Technical data sheet

Joint cover, for trunking, type WDK 60110

Item number: 6193598



Dimensions

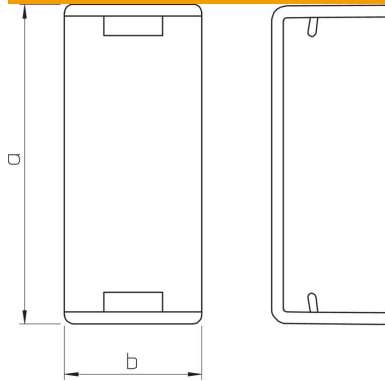

Length	18 mm
Width	113 mm
Height	62 mm
Dimension a	113 mm
Dimension b	18 mm

Technical data

Version for	Trunking cut cover
Fastening type	Lockable
Shape	Symmetrical
Halogen-free	no
Protection rating	IP30
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C