

Technical data sheet

T piece cover, for trunking type WDK 25040

Item number: 6192491



T piece cover for changing the direction of the WDK trunking.



PVC Polyvinylchloride

Master data	
Item number	6192491
Description 1	T piece hood
Manufacturer	OBO
Dimension	25x40mm
Colour	Pure white; RAL 9010
Material	Polyvinylchloride
Smallest sales unit	4
Unit of quantity	Piece
Weight	1.994 kg
Weight unit	kg/100 pc.


Technical data sheet

T piece cover, for trunking type WDK 25040

Item number: 6192491



Dimensions

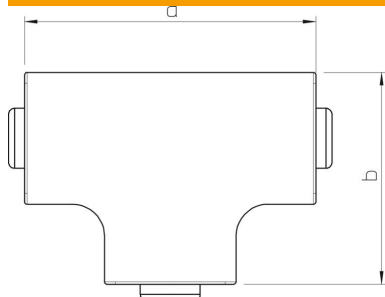

Length	83 mm
Width	40 mm
Height	25 mm
Dimension a	83 mm
Dimension b	63 mm
Dimension H	40 mm

Technical data

Version for	Hood fitting
Fastening type	Lockable
Maintain electrical functions	no
for duct dimension	25 x 40
Halogen-free	no
Trunking depth	25 mm
Protection rating	IP30
Protective film	no
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C