


# Technical data sheet

T piece cover, for trunking type WDK 30030

Item number: 6182887



T piece hood for changing the direction of the WDK trunking.

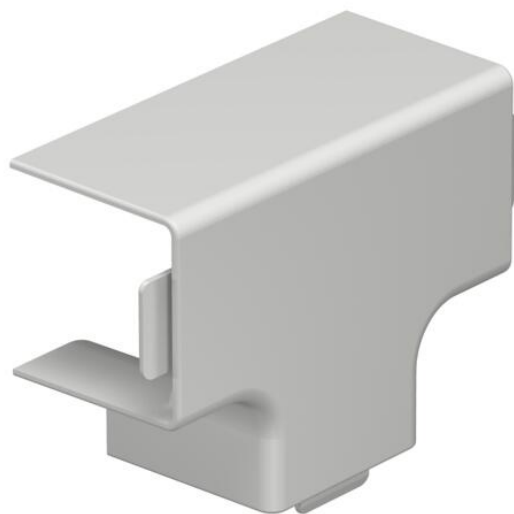

**PVC** Polyvinylchloride

| Master data         |                      |
|---------------------|----------------------|
| Item number         | 6182887              |
| Description 1       | T piece hood         |
| Manufacturer        | OBO                  |
| Dimension           | 30x30mm              |
| Colour              | Light grey; RAL 7035 |
| Material            | Polyvinylchloride    |
| Smallest sales unit | 4                    |
| Unit of quantity    | Piece                |
| Weight              | 1.485 kg             |
| Weight unit         | kg/100 pc.           |


# Technical data sheet

T piece cover, for trunking type WDK 30030

Item number: 6182887



## Dimensions

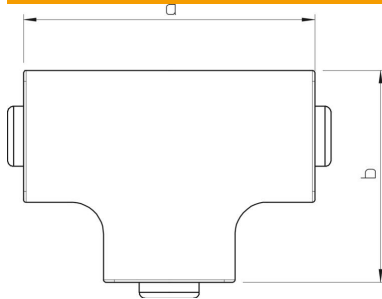

|             |       |
|-------------|-------|
| Length      | 50 mm |
| Width       | 30 mm |
| Height      | 30 mm |
| Dimension a | 50 mm |
| Dimension b | 39 mm |
| Dimension H | 30 mm |

## Technical data

|                                   |              |
|-----------------------------------|--------------|
| Version for                       | Hood fitting |
| Fastening type                    | Lockable     |
| Maintain electrical functions     | no           |
| for duct dimension                | 30 x 30      |
| Halogen-free                      | no           |
| Trunking depth                    | 30 mm        |
| Protection rating                 | IP30         |
| Protective film                   | no           |
| Protection rating IK code         | IK04         |
| Permitted temperature range, max. | 60 °C        |
| Permitted temperature range, min. | -5 °C        |