

Technical data sheet

T piece, for trunking type WDK 100130

Item number: 6193410



T piece to change the direction of the WDK trunking.



PVC Polyvinylchloride

Master data	
Item number	6193410
Description 1	T piece
Manufacturer	OBO
Dimension	400x130x100
Colour	Stone grey; RAL 7030
Material	Polyvinylchloride
Smallest sales unit	1
Unit of quantity	Piece
Weight	120 kg
Weight unit	kg/100 pc.


Technical data sheet

T piece, for trunking type WDK 100130

Item number: 6193410



Dimensions

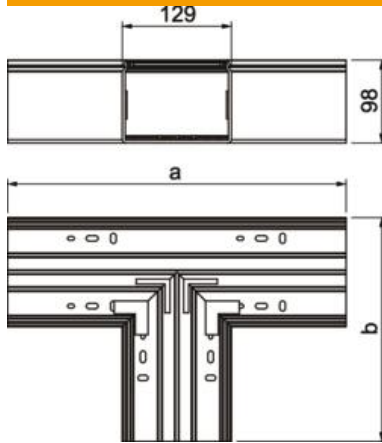

Length	400 mm
Width	130 mm
Height	100 mm
Dimension a	400 mm

Technical data

Version for	Base
Fastening type	Base perforation
Halogen-free	no
Protection rating	IP30
Protective film	no
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C