

Technical data sheet

T piece, for trunking type WDK 100230

Item number: 6193412



T piece to change the direction of the WDK trunking.



PVC Polyvinylchloride

Master data

Item number	6193412
Type	WDK T100230GR
Description 1	T piece
Manufacturer	OBO
Dimension	600x230x100
Colour	Stone grey; RAL 7030
Material	Polyvinylchloride
Smallest sales unit	1
Unit of quantity	Piece
Weight	248.8 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	7,2035 kg CO2e / 1 Piece


Technical data sheet

T piece, for trunking type WDK 100230

Item number: 6193412



Dimensions

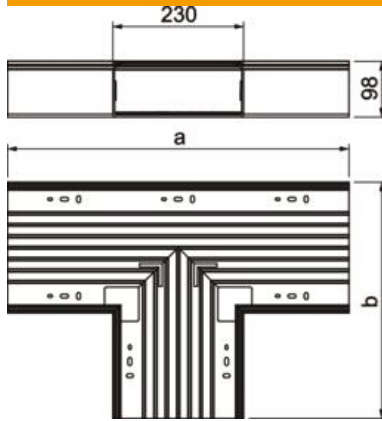

Length	600 mm
Width	230 mm
Height	100 mm
Dimension a	600 mm

Technical data

Version for	Base
Fastening type	Base perforation
Halogen-free	no
Protection rating	IP30
Protective film	no
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C