

Technical data sheet

T piece, for trunking type WDK 100230

Item number: 6163092



T piece to change the direction of the WDK trunking.



PVC Polyvinylchloride

Master data		
Item number	6163092	
Type	WDK T100230LGR	
Description 1	T piece	
Manufacturer	OBO	
Dimension	600x230x100	
Colour	Light grey; RAL 7035	
Material	Polyvinylchloride	
Smallest sales unit	1	
Unit of quantity	Piece	
Weight	248.8 kg	
Weight unit	kg/100 pc.	
CO2 Footprint (GWP) Cradle-to-Gate	6,6972 kg CO2e / 1 Piece	


Technical data sheet

T piece, for trunking type WDK 100230

Item number: 6163092



Dimensions

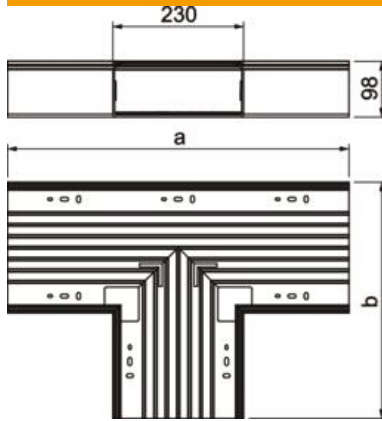

Length	600 mm
Width	230 mm
Height	100 mm
Dimension a	600 mm

Technical data

Version for	Base
Fastening type	Base perforation
Halogen-free	no
Protection rating	IP30
Protective film	no
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C