


# Technical data sheet

## Roof-form cover

Item number: 6227269

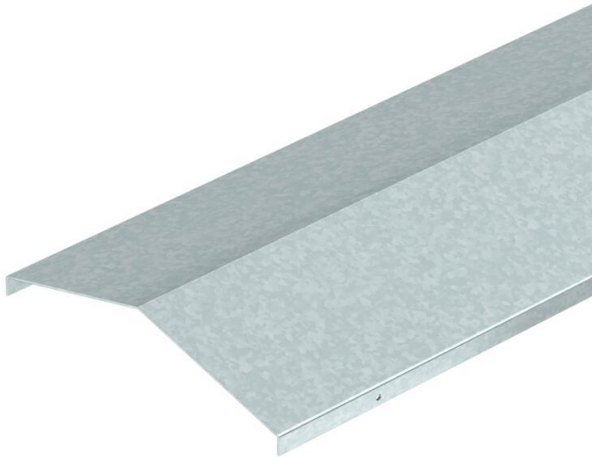

Roof-shaped cover for installing on cable trays, cable ladders and wide span systems. Self-tapping drilling screws are used for fastening. The screws are not included in the scope of delivery.



St	Steel
FT	Hot-dip galvanised

### Master data

Item number	6227269
Type	WDRLU DF11166FT
Description 1	Roof-shaped cover
Description 2	wide span system 110 and 160
Manufacturer	OBO
Dimension	600x3000x2mm
Colour	zinc
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	3
Unit of quantity	Metre
Weight	1086.933 kg
Weight unit	kg/100 m
CO2 Footprint (GWP) Cradle-to-Gate	24,231 kg CO2e / 1 Meter


# Technical data sheet

## Roof-form cover


Item number: 6227269



### Dimensions

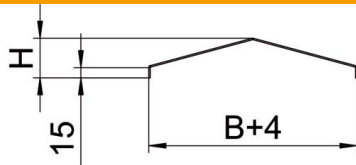

Length	3,000 mm
Width	600 mm
Height	98 mm
Plate thickness	2 mm
Dimension B	600 mm
Dimension H	98 mm
Dimension L	3,000 mm

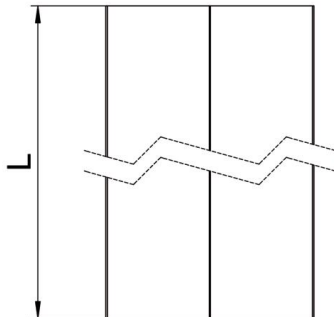

### Technical data

Fastening type	Screw-on
Maintain electrical functions	no
Suitable for mesh cable tray	no
Suitable for cable ladder	yes
Suitable for cable tray	yes
Rustproof steel, pickled	no