

Technical data sheet

Cover with turn buckle A2

Item number: 6227360



Cover for wide span trays and ladders with the side height 110 and 160 mm.
Transverse bead from 500 mm width.
Take appropriate constructive protection measures if there are high wind speeds.



A2 Stainless steel

2B Bright, treated

Master data

Item number	6227360
Type	WDRL 1116 20 A2
Description 1	Cover with turn buckle
Description 2	wide span system 110 and 160
Manufacturer	OBO
Dimension	200x3000
Colour	stainless steel
Material	Stainless steel
Surface	Bright, treated
Surface standard	
Smallest sales unit	3
Unit of quantity	Metre
Weight	186.67 kg
Weight unit	kg/100 m
CO2 Footprint (GWP) Cradle-to-Gate	9,9391 kg CO2e / 1 Meter


Technical data sheet

Cover with turn buckle A2

Item number: 6227360



Dimensions

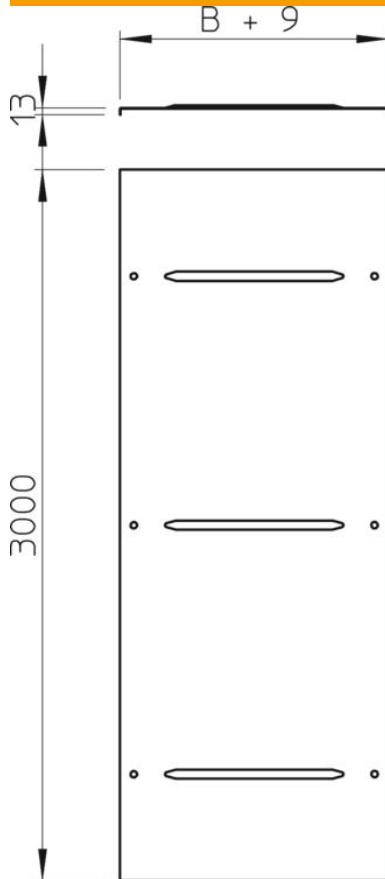

Length	3,000 mm
Width	200 mm
Height	13 mm
Plate thickness	1.5 mm
Dimension B	200 mm
Dimension H	15 mm
Dimension L	3,000 mm

Technical data

Number of turn buckles	6 St.
Fastening type	Sash lock
Maintain electrical functions	no
Suitable for mesh cable tray	no
Suitable for cable ladder	yes
Suitable for cable tray	yes
Rustproof steel, pickled	no