


Technical data sheet

Cover for T branch piece DD

Item number: 6231705

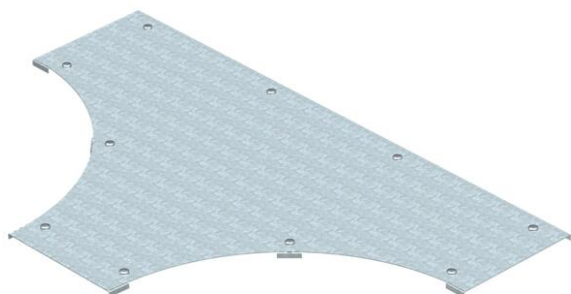

Cover for wide span T branch piece with pre-mounted turn buckles.
As the connector is mounted from the outside, the fitting cover is 300 mm shorter than the corresponding fitting. This must be considered when installing the track elements.




St Steel

DD Strip galvanised zinc/aluminium, Double Dip

Master data

| | |
|------------------------------------|---|
| Item number | 6231705 |
| Type | WDTRL 600 DD |
| Description 1 | Cover, T-branch piece |
| Description 2 | wide span system 110 and 160 |
| Manufacturer | OBO |
| Dimension | B600mm |
| Colour | zinc |
| Material | Steel |
| Surface | Strip galvanised zinc/aluminium, Double Dip |
| Surface standard | DIN EN 10346 |
| Smallest sales unit | 1 |
| Unit of quantity | Piece |
| Weight | 1729.5 kg |
| Weight unit | kg/100 pc. |
| CO2 Footprint (GWP) Cradle-to-Gate | 70,416 kg CO2e / 1 Piece |

Dimensions

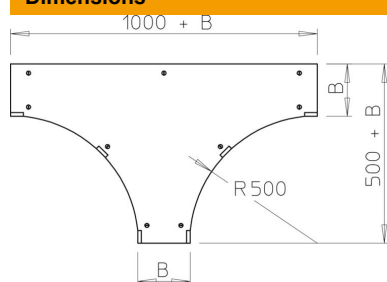

| | |
|-----------------|---------|
| Width | 600 mm |
| Plate thickness | 1.25 mm |
| Dimension B | 600 mm |
| Dimension H | 15 mm |

Technical data sheet

Cover for T branch piece DD

Item number: 6231705



Technical data

| | |
|---------------------------|-----------|
| Number of turn buckles | 9 St. |
| Fastening type | Sash lock |
| Suitable for cable ladder | yes |
| Suitable for cable tray | yes |
| Material thickness | 1.25 mm |
| Rustproof steel, pickled | no |