

Technical data sheet

Foot plate for wide-span systems

Item number: 6232500



Base plate for accepting wide span systems, for example, for vertical routing of wide span cable trays.
Including appropriate bolts, washers and nuts.



- St

Steel
- FT

Hot-dip galvanised

Master data

Item number	6232500
Type	WFP 110 FT
Description 1	Base plate
Description 2	for wide span system 110
Manufacturer	OBO
Colour	zinc
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	1
Unit of quantity	Piece
Weight	266.2 kg
Weight unit	kg/100 pc.


Technical data sheet

Foot plate for wide-span systems

Item number: 6232500



Dimensions

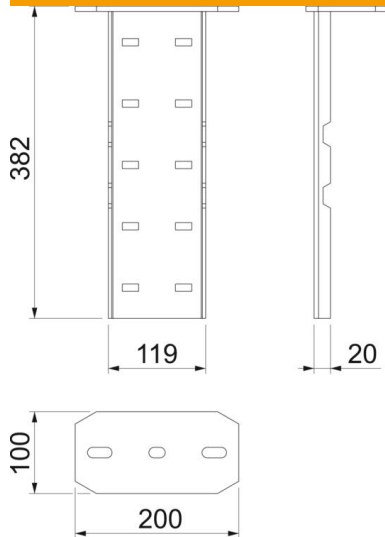

Length	380 mm
Width	200 mm
Height	110 mm

Technical data

Version for	Screw head plate
Suitable for panel fastening	no
Suitable for profile shapes	C profile
Rustproof steel, pickled	no
Angle range, max.	90 mm
Angle range, min.	90 mm