

Technical data sheet

Foot plate for wide-span systems

Item number: 6232510



Foot plate to accept wide-span systems, e.g. for vertical routing of wide-span cable trays. Including screws, washers and nuts.



- St

Steel
- FT

Hot-dip galvanised

Master data

Item number	6232510
Description 1	Base plate
Description 2	for wide span system 160
Manufacturer	OBO
Dimension	160
Colour	zinc
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	1
Unit of quantity	Piece
Weight	333 kg
Weight unit	kg/100 pc.


# Technical data sheet

## Foot plate for wide-span systems

Item number: 6232510



### Dimensions

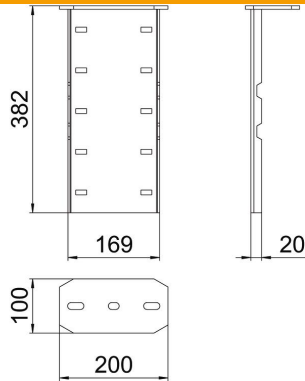

Length	382 mm
Width	169 mm
Height	20 mm

### Technical data

Version for	Screw head plate
Maintain electrical functions	no
Suitable for ceiling fastening	no
Suitable for panel fastening	no
Suitable for profile shapes	C profile
Rustproof steel, pickled	no
Angle range, max.	90 mm
Angle range, min.	90 mm