

Technical data sheet

90° bend 110 A2

Item number: 6312543



90° bend, horizontal, for all wide span cable ladders of 110 mm side height.
For further stabilisation, additional supports should be planned for the area of the fittings.




A2	Stainless steel
2B	Bright, treated

Master data

Item number	6312543
Description 1	90° bend
Description 2	for wide span cable ladder 110
Manufacturer	OBO
Dimension	110x400
Colour	stainless steel
Material	Stainless steel
Surface	Bright, treated
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	1052.1 kg
Weight unit	kg/100 pc.

Dimensions

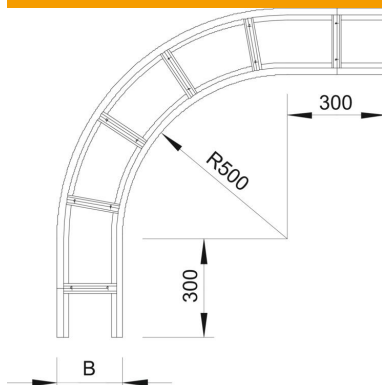

Width	400 mm
Height	110 mm
Dimension B	400 mm
Dimension R	400 mm

Technical data sheet

90° bend 110 A2

Item number: 6312543



Technical data

Bend (angle)	90°
Version of the rungs	Profile unperforated
Maintain electrical functions	no
Change of direction	Horizontal
Rustproof steel, pickled	no
Side perforation	no
Wide-span version	yes
Rail thickness	2 mm