

Technical data sheet

90° bend 160 FT

Item number: 6229433



90° bend, horizontal, for all wide span cable ladders of 160 mm side height.
For further stabilisation, additional supports should be planned for the area of the fittings.




St	Steel
FT	Hot-dip galvanised

Master data

Item number	6229433
Type	WLB 90 163 FT
Description 1	90° bend
Description 2	for wide span cable ladder 160
Manufacturer	OBO
Dimension	160x300
Colour	zinc
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	1
Unit of quantity	Piece
Weight	1310 kg
Weight unit	kg/100 pc.

Dimensions

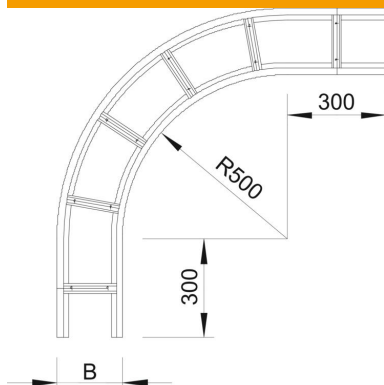

Width	300 mm
Height	160 mm
Dimension B	300 mm
Dimension R	300 mm

Technical data sheet

90° bend 160 FT

Item number: 6229433



Technical data

Bend (angle)	90°
Version of the rungs	Profile unperforated
Side rail version	Flat profile
Maintain electrical functions	no
Change of direction	Horizontal
Rustproof steel, pickled	no
Side perforation	no
Wide-span version	yes
Rail thickness	2 mm