

Technical data sheet

90° bend 160 FT

Item number: 6229468




90° bend, horizontal, for all wide span cable ladders of 160 mm side height.
For further stabilisation, additional supports should be planned for the area of the fittings.



St	Steel
FT	Hot-dip galvanised

Master data		
Item number	6229468	
Description 1	90° bend	
Description 2	for wide span cable ladder 160	
Manufacturer	OBO	
Dimension	160x500	
Colour	zinc	
Material	Steel	
Surface	Hot-dip galvanised	
Surface standard	DIN EN ISO 1461	
Smallest sales unit	1	
Unit of quantity	Piece	
Weight	1576 kg	
Weight unit	kg/100 pc.	

Dimensions		
Width	500 mm	
Height	160 mm	
Dimension B	500 mm	
Dimension R	500 mm	

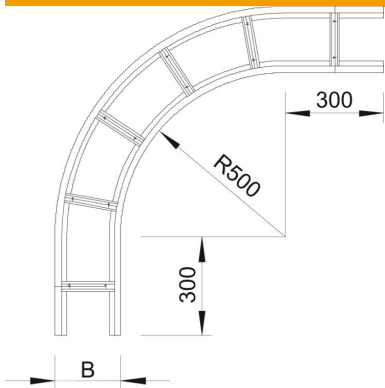

Technical data sheet

90° bend 160 FT

Item number: 6229468



Technical data

Bend (angle)	90°
Version of the rungs	Profile unperforated
Side rail version	Flat profile
Maintain electrical functions	no
Change of direction	Horizontal
Rustproof steel, pickled	no
Side perforation	no
Wide-span version	yes
Rail thickness	2 mm