

Technical data sheet

90° bend 200 FT

Item number: 6233449



90° bend, horizontal, for all wide span cable ladders of 200 mm side height.
For further stabilisation, additional supports should be planned for the area of the fittings.



St

Steel


FT

Hot-dip galvanised

Master data

Item number	6233449
Type	WLB 90 2040 FT
Description 1	90° bend
Description 2	for wide span cable ladder 200
Manufacturer	OBO
Dimension	200x400
Colour	zinc
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	1
Unit of quantity	Piece
Weight	2241 kg
Weight unit	kg/100 pc.

Dimensions

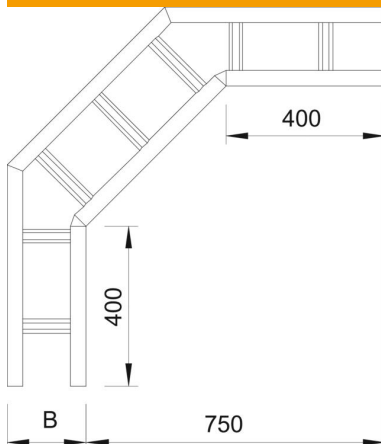

Width	400 mm
Height	200 mm
Dimension B	400 mm
Dimension R	400 mm

Technical data sheet

90° bend 200 FT

Item number: 6233449



Technical data

Bend (angle)	90°
Version of the rungs	Profile unperforated
Side rail version	Flat profile
Maintain electrical functions	no
Change of direction	Horizontal
Rustproof steel, pickled	no
Side perforation	no
Wide-span version	yes
Rail thickness	2.5 mm