


Technical data sheet

Toolless cable clip, cable diameter 60–85 mm

Item number: 1198660

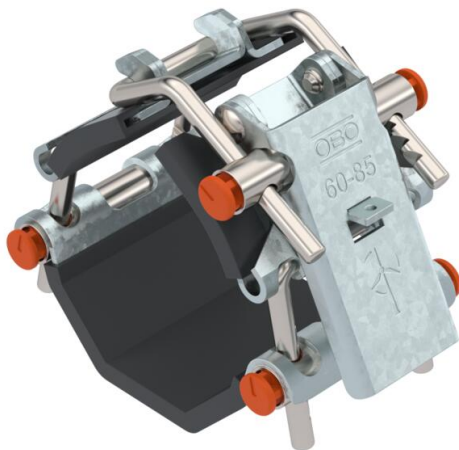

Cable clip for the mounting of cables with a large diameter of 60 mm to 85 mm. The diameter can be adjusted without tools. Fastening on a profile rail with hammer-head bolt, washer and nut. Maximum axial load capacity of 150 kg. Application in a temperature range of –40 °C to +90 °C.



Master data

Item number	1198660
Type	WLKS 60-85
Description 1	Toolless cable clamp
Description 2	for 60-85 mm cable
Manufacturer	OBO
Dimension	60-85
Smallest sales unit	20
Unit of quantity	Piece
Weight	71 kg
Weight unit	kg/100 pc.

 
Technical data sheet

Toolless cable clip, cable diameter 60–85 mm

Item number: 1198660



Dimensions



Length	125 mm
Width	72 mm
Height	110 mm
Plate thickness	2 mm

Technical data

Number of cables/pipes	1
For pipe diameter, max.	85 mm
For pipe diameter, min.	60 mm
Cable diameter, max.	85 mm
Cable diameter, min.	60 mm
Mounting type	Profile rail
Clamping range D, max.	85 mm
Clamping range D, min.	60 mm