

Technical data sheet

T branch piece 110 FS

Item number: 6312632



Horizontal T branch piece, for all wide span cable ladders of 110 mm side height.
For further stabilisation, additional supports should be planned for the area of the fittings.




St	Steel
FS	Strip galvanized

Master data

Item number	6312632
Description 1	T-branch piece
Description 2	for wide span cable ladder 110
Manufacturer	OBO
Dimension	110x200
Colour	zinc
Material	Steel
Surface	Strip galvanized
Surface standard	DIN EN 10346
Smallest sales unit	1
Unit of quantity	Piece
Weight	1760 kg
Weight unit	kg/100 pc.

Dimensions

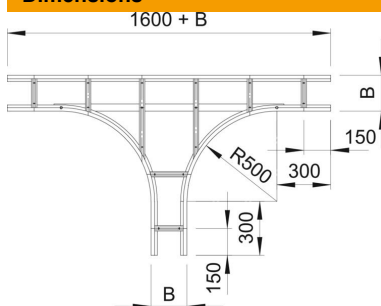

Width	200 mm
Height	110 mm
Dimension B	200 mm
Dimension R	500 mm

Technical data sheet

T branch piece 110 FS

Item number: 6312632



Technical data

Version of the rungs	Profile unperforated
Side rail version	Flat profile
Type	Exit symmetrical
Maintain electrical functions	no
Rustproof steel, pickled	no
Wide-span version	yes
Rail thickness	2 mm