

Technical data sheet

T branch piece 110 A4

Item number: 6312817



Horizontal T branch piece, for all wide span cable ladders of 110 mm side height.
For further stabilisation, additional supports should be planned for the area of the fittings.




A4 Stainless steel

2B Bright, treated

Master data

Item number	6312817
Type	WLT 1130 A4
Description 1	T-branch piece
Description 2	for wide span cable ladder 110
Manufacturer	OBO
Dimension	110x300
Colour	stainless steel
Material	Stainless steel
Surface	Bright, treated
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	1870 kg
Weight unit	kg/100 pc.

Dimensions

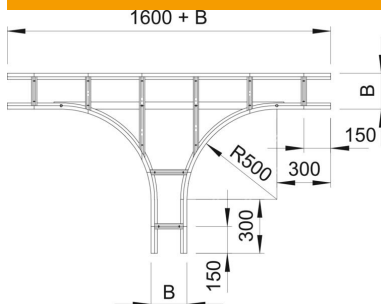

Width	300 mm
Height	110 mm
Dimension B	300 mm
Dimension R	500 mm

Technical data sheet

T branch piece 110 A4

Item number: 6312817



Technical data

Version of the rungs	Profile unperforated
Side rail version	Flat profile
Type	Exit symmetrical
Maintain electrical functions	no
Rustproof steel, pickled	no
Wide-span version	yes
Rail thickness	2 mm