


Technical data sheet

T branch piece 110 FT

Item number: 6312756

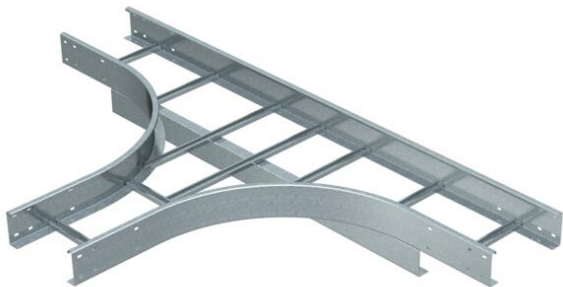

Horizontal T branch piece, for all wide span cable ladders of 110 mm side height.
For further stabilisation, additional supports should be planned for the area of the fittings.




- St Steel
- FT Hot-dip galvanised

Master data

Item number	6312756
Type	WLT 1150 FT
Description 1	T-branch piece
Description 2	for wide span cable ladder 110
Manufacturer	OBO
Dimension	110x500
Colour	zinc
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	1
Unit of quantity	Piece
Weight	2275 kg
Weight unit	kg/100 pc.

Dimensions

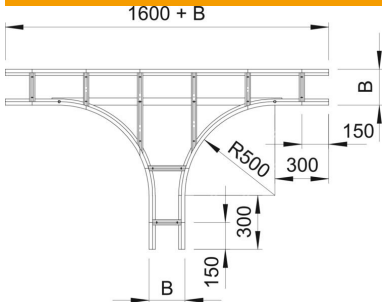

Width	500 mm
Height	110 mm
Dimension B	500 mm
Dimension R	500 mm

Technical data sheet

T branch piece 110 FT

Item number: 6312756



Technical data

Version of the rungs	Profile unperforated
Side rail version	Flat profile
Type	Exit symmetrical
Maintain electrical functions	no
Rustproof steel, pickled	no
Wide-span version	yes
Rail thickness	2 mm