

# Technical data sheet

## T branch piece 110 A4

Item number: 6312823



Horizontal T branch piece, for all wide span cable ladders of 110 mm side height.  
For further stabilisation, additional supports should be planned for the area of the fittings.




**A4** Stainless steel

**2B** Bright, treated

### Master data

Item number	6312823
Type	WLT 1160 A4
Description 1	T-branch piece
Description 2	for wide span cable ladder 110
Manufacturer	OBO
Dimension	110x600
Colour	stainless steel
Material	Stainless steel
Surface	Bright, treated
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	2340 kg
Weight unit	kg/100 pc.

### Dimensions

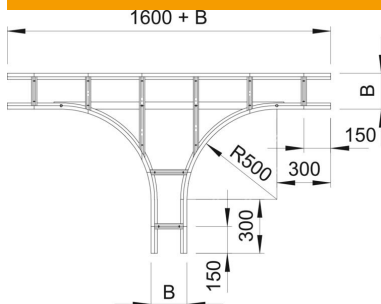

Width	600 mm
Height	110 mm
Dimension B	600 mm
Dimension R	500 mm

# Technical data sheet

T branch piece 110 A4

Item number: 6312823



## Technical data

Version of the rungs	Profile unperforated
Side rail version	Flat profile
Type	Exit symmetrical
Maintain electrical functions	no
Rustproof steel, pickled	no
Wide-span version	yes
Rail thickness	2 mm