

Technical data sheet

T branch piece 110 FT

Item number: 6312764



Horizontal T branch piece, for all wide span cable ladders of 110 mm side height.
For further stabilisation, additional supports should be planned for the area of the fittings.




St Steel

FT Hot-dip galvanised

Master data

Item number	6312764
Type	WLT 1160 FT
Description 1	T-branch piece
Description 2	for wide span cable ladder 110
Manufacturer	OBO
Dimension	110x600
Colour	zinc
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	1
Unit of quantity	Piece
Weight	2404 kg
Weight unit	kg/100 pc.

Dimensions

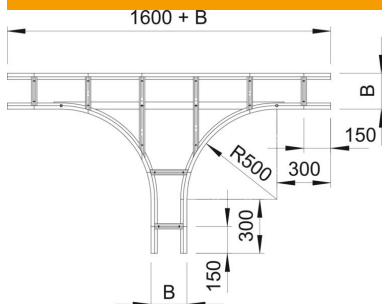

Width	600 mm
Height	110 mm
Dimension B	600 mm
Dimension R	500 mm

Technical data sheet

T branch piece 110 FT

Item number: 6312764



Technical data

Version of the rungs	Profile unperforated
Side rail version	Flat profile
Type	Exit symmetrical
Maintain electrical functions	no
Rustproof steel, pickled	no
Wide-span version	yes
Rail thickness	2 mm