


# Technical data sheet

## T branch piece 160, A4

Item number: 6229822

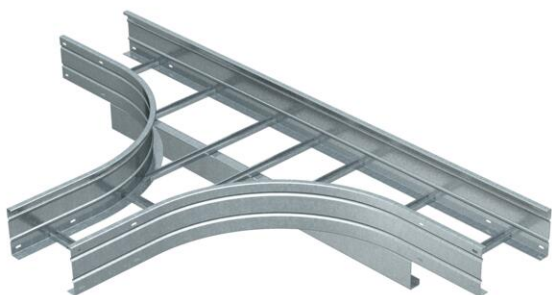

Horizontal T branch piece, for all wide span cable ladders of 160 mm side height. For further stabilisation, additional supports should be planned for the area of the fittings.




**A4** Stainless steel

**2B** Bright, treated

### Master data

Item number	6229822
Type	WLT 1630 A4
Description 1	T-branch piece
Description 2	for wide span cable ladder 160
Manufacturer	OBO
Dimension	160x300
Colour	stainless steel
Material	Stainless steel
Surface	Bright, treated
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	2452 kg
Weight unit	kg/100 pc.

### Dimensions

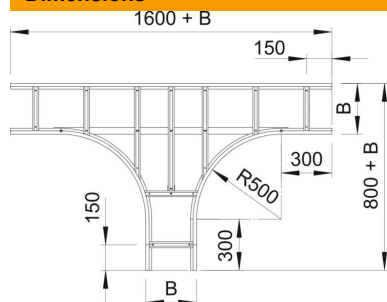

Width	300 mm
Height	160 mm
Dimension B	300 mm
Dimension R	500 mm

# Technical data sheet

T branch piece 160, A4

Item number: 6229822



## Technical data

Version of the rungs	Profile unperforated
Side rail version	Flat profile
Maintain electrical functions	no
Rustproof steel, pickled	no
Wide-span version	yes
Rail thickness	2 mm