


Technical data sheet

T branch piece 160, A4

Item number: 6229824

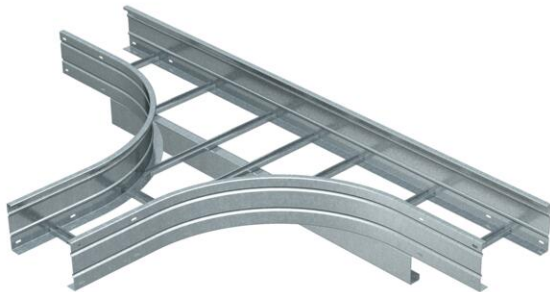

Horizontal T branch piece, for all wide span cable ladders of 160 mm side height. For further stabilisation, additional supports should be planned for the area of the fittings.




A4 Stainless steel

2B Bright, treated

Master data

Item number	6229824
Type	WLT 1640 A4
Description 1	T-branch piece
Description 2	for wide span cable ladder 160
Manufacturer	OBO
Dimension	160x400
Colour	stainless steel
Material	Stainless steel
Surface	Bright, treated
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	2604 kg
Weight unit	kg/100 pc.

Dimensions

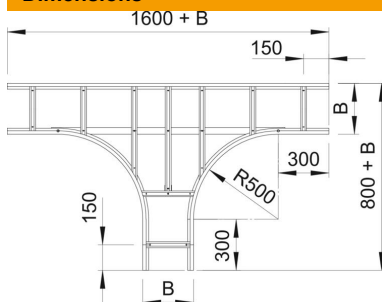

Width	400 mm
Height	160 mm
Dimension B	400 mm
Dimension R	500 mm

Technical data sheet

T branch piece 160, A4

Item number: 6229824



Technical data

Version of the rungs	Profile unperforated
Side rail version	Flat profile
Maintain electrical functions	no
Rustproof steel, pickled	no
Wide-span version	yes
Rail thickness	2 mm