


Technical data sheet

T branch piece 160 FT

Item number: 6229778

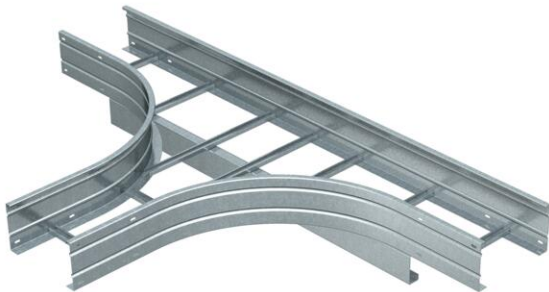

Horizontal T branch piece, for all wide span cable ladders of 160 mm side height.
For further stabilisation, additional supports should be planned for the area of the fittings.



St

Steel

FT

Hot-dip galvanised

Master data

Item number	6229778
Type	WLT 1660 FT
Description 1	T-branch piece
Description 2	for wide span cable ladder 160
Manufacturer	OBO
Dimension	160x600
Colour	zinc
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	1
Unit of quantity	Piece
Weight	3040 kg
Weight unit	kg/100 pc.

Dimensions

Width	600 mm
Height	160 mm
Dimension B	600 mm
Dimension R	500 mm

Technical data

Version of the rungs	Profile unperforated
Side rail version	Flat profile
Maintain electrical functions	no
Rustproof steel, pickled	no
Wide-span version	yes
Rail thickness	2 mm