


# Technical data sheet

## Fastening clip, plant standard 7855, single-lobe

Item number: 1043196

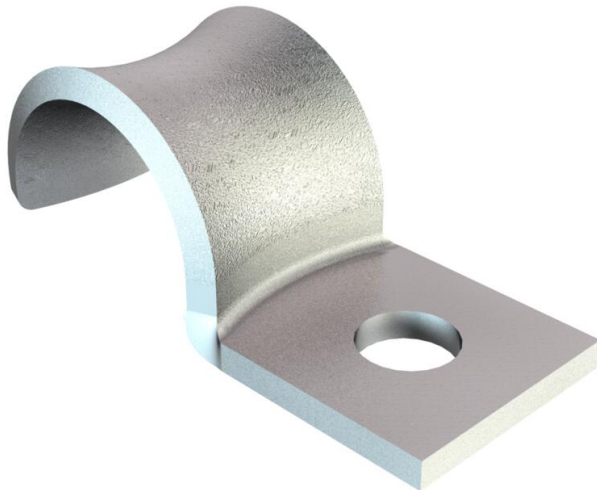

Dimensions to Siemens standard SN 78550, shape A, with strongly rounded edges, thus particularly suitable for sensitive cables.

\* Sizes 2 to 10 not suitable for bolt-firing tool and nail device.



**St** Steel

**GTP** Electrogalvanized, transparently passivated

### Master data

|                                    |                                             |
|------------------------------------|---------------------------------------------|
| Item number                        | 1043196                                     |
| Type                               | WN 7855 A 10                                |
| Description 1                      | Fastening clip                              |
| Description 2                      | single lobe                                 |
| Manufacturer                       | OBO                                         |
| Dimension                          | 10mm                                        |
| Material                           | Steel                                       |
| Surface                            | Electrogalvanized, transparently passivated |
| Surface standard                   |                                             |
| Smallest sales unit                | 100                                         |
| Unit of quantity                   | Piece                                       |
| Weight                             | 0.17 kg                                     |
| Weight unit                        | kg/100 pc.                                  |
| CO2 Footprint (GWP) Cradle-to-Gate | 0,0044 kg COe / 1 Piece                     |


# Technical data sheet

Fastening clip, plant standard 7855, single-lobe

Item number: 1043196



## Dimensions

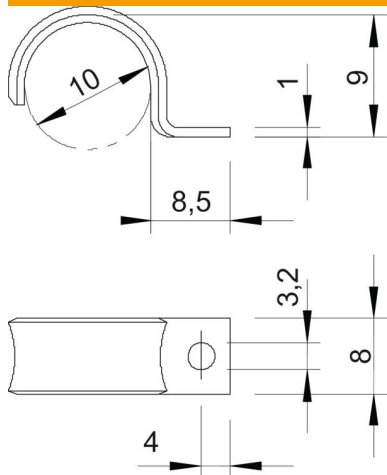

|             |        |
|-------------|--------|
| Length      | 8.5 mm |
| Width       | 8 mm   |
| Height      | 9 mm   |
| Dimension A | 4 mm   |
| Dimension b | 8 mm   |
| Dimension D | 10 mm  |
| Dimension d | 3.2 mm |
| Dimension H | 9 mm   |
| Dimension L | 8.5 mm |
| Dimension t | 1 mm   |

## Technical data

|                                  |             |
|----------------------------------|-------------|
| Distance to the wall             | no          |
| Number of cables/pipes           | 1           |
| Version for                      | Single-lobe |
| Fastening type                   | Screw hole  |
| For diameter                     | 10          |
| Suitable in fire protection area | no          |
| Halogen-free                     | yes         |
| Plastic-covered                  | no          |
| Hole size                        | 3,2 mm      |
| Material thickness               | 1.5 mm      |
| Nominal diameter                 | 10 mm       |
| UV-resistant                     | yes         |