


Technical data sheet

Fastening clip, plant standard 7855, single-lobe

Item number: 1043021

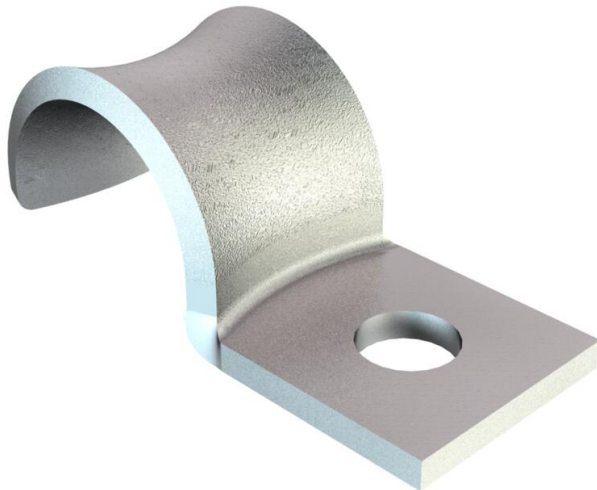

Dimensions to Siemens standard SN 78550, shape A, with strongly rounded edges, thus particularly suitable for sensitive cables.

* Sizes 2 to 10 not suitable for bolt-firing tool and nail device.



St

Steel

GTP

Electrogalvanized, transparently passivated

Master data

Item number	1043021
Type	WN 7855 A 2.5
Description 1	Fastening clip
Description 2	single lobe
Manufacturer	OBO
Dimension	2,5mm
Material	Steel
Surface	Electrogalvanized, transparently passivated
Surface standard	
Smallest sales unit	100
Unit of quantity	Piece
Weight	0.041 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0014 kg COe / 1 Piece


Technical data sheet

Fastening clip, plant standard 7855, single-lobe

Item number: 1043021



Dimensions

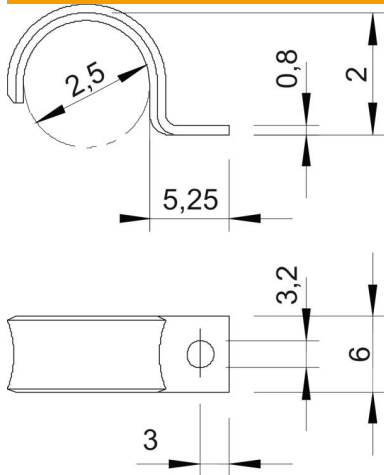

Length	5.25 mm
Width	6 mm
Height	2 mm
Dimension A	3 mm
Dimension b	6 mm
Dimension D	2.5 mm
Dimension d	3.2 mm
Dimension H	2 mm
Dimension L	5.25 mm
Dimension t	0.8 mm

Technical data

Distance to the wall	no
Number of cables/pipes	1
Version for	Single-lobe
Fastening type	Screw hole
For diameter	2,5
Suitable in fire protection area	no
Halogen-free	yes
Plastic-covered	no
Hole size	3,2 mm
Material thickness	0.8 mm
Nominal diameter	2.5 mm
UV-resistant	yes