


Technical data sheet

Fastening clip, plant standard 7855, single-lobe

Item number: 1043102

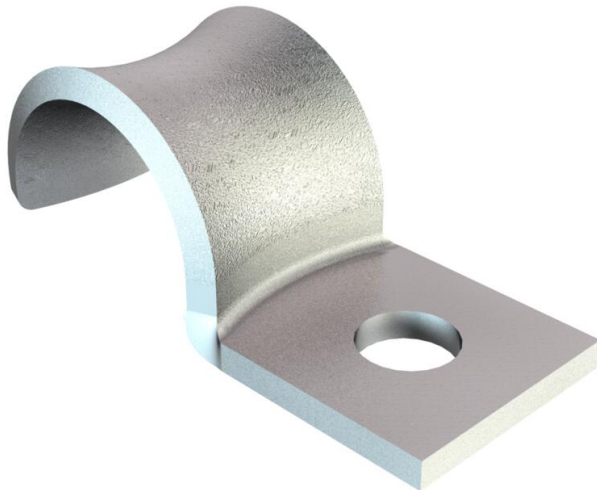

Dimensions to Siemens standard SN 78550, shape A, with strongly rounded edges, thus particularly suitable for sensitive cables.

* Sizes 2 to 10 not suitable for bolt-firing tool and nail device.



St Steel

GTP Electrogalvanized, transparently passivated

Master data

Item number	1043102
Type	WN 7855 A 6
Description 1	Fastening clip
Description 2	single lobe
Manufacturer	OBO
Dimension	6mm
Material	Steel
Surface	Electrogalvanized, transparently passivated
Surface standard	
Smallest sales unit	100
Unit of quantity	Piece
Weight	0.082 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0029 kg COe / 1 Piece


Technical data sheet

Fastening clip, plant standard 7855, single-lobe

Item number: 1043102



Dimensions

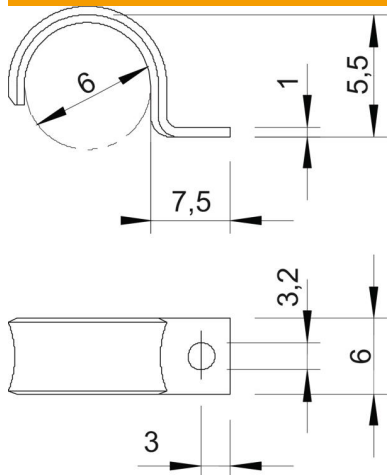

Length	7.5 mm
Width	6 mm
Height	5.5 mm
Dimension A	3 mm
Dimension b	6 mm
Dimension D	6 mm
Dimension d	3.2 mm
Dimension H	5.5 mm
Dimension L	7.5 mm
Dimension t	1 mm

Technical data

Distance to the wall	no
Number of cables/pipes	1
Version for	Single-lobe
Fastening type	Screw hole
For diameter	6
Suitable in fire protection area	no
Halogen-free	yes
Plastic-covered	no
Hole size	3.2 mm
Material thickness	1 mm
Nominal diameter	6 mm
UV-resistant	yes