


Technical data sheet

90° bend 110 FT

Item number: 6098352

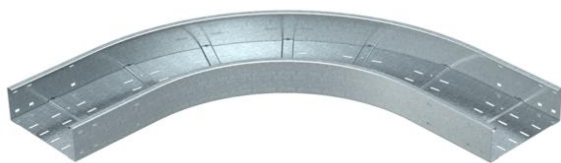

90° bend, horizontal, for all wide span cable trays of 110 mm side height.
For further stabilisation, additional supports should be planned for the area of the fittings.




St Steel

FT Hot-dip galvanised

Master data

Item number	6098352
Description 1	90° bend
Description 2	for wide span cable tray 110
Manufacturer	OBO
Dimension	110x400
Colour	zinc
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	1
Unit of quantity	Piece
Weight	1747.4 kg
Weight unit	kg/100 pc.

Dimensions

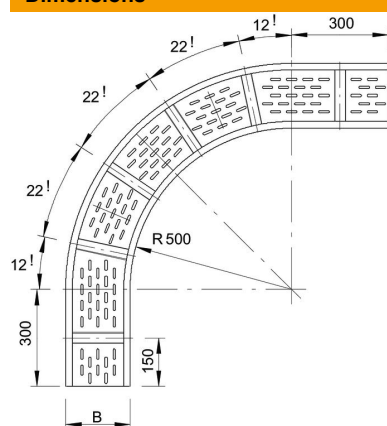

Width	400 mm
Height	110 mm
Plate thickness	2 mm
Dimension B	400 mm

Technical data sheet

90° bend 110 FT

Item number: 6098352



Technical data

Bend (angle)	90°
Connector version	Without connectors
Mounting perforation in base	yes
Change of direction	Horizontal
Rustproof steel, pickled	no
Side perforation	no
Wide-span version	yes
Type of connector, cable support system	Screwed