


Technical data sheet

Straight connector A2

Item number: 6227724

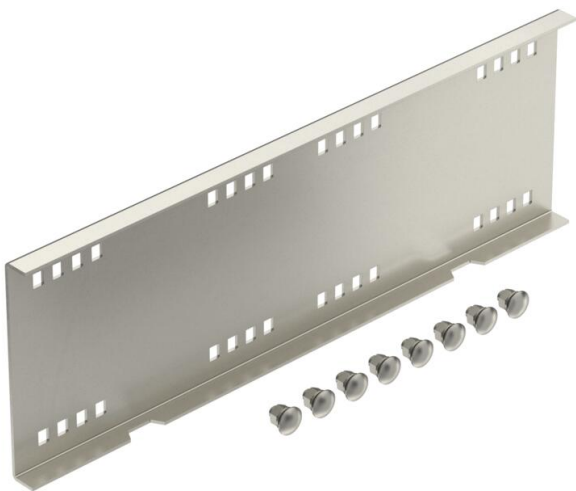

Straight connector for straight connections of cable trays, wide span cable trays and ladders with a side height of 160 mm.
Including appropriate bolts, washers and nuts.



A2	Stainless steel
2B	Bright, treated

Master data	
Item number	6227724
Type	WRVL 160 A2
Description 1	Straight connector
Description 2	for wide span system 160
Manufacturer	OBO
Dimension	160x500
Colour	stainless steel
Material	Stainless steel
Surface	Bright, treated
Surface standard	
Smallest sales unit	2
Unit of quantity	Piece
Weight	218 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	13,232 kg CO2e / 1 Piece


Technical data sheet

Straight connector A2

Item number: 6227724



Dimensions

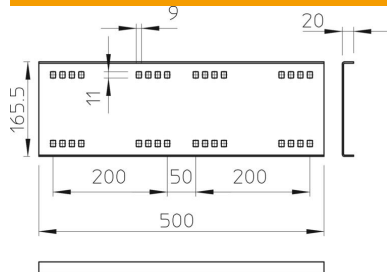

Length	500 mm
Width	20 mm
Height	160 mm
Plate thickness	2.5 mm

Technical data

Version for	Straight connector
Maintain electrical functions	no
Suitable for mesh cable tray	no
Suitable for cable ladder	yes
Suitable for cable tray	yes
Suitable for cable tray system height	160 mm
Adjustable connector, horizontal	no
Articulated connector, vertical	no
Rustproof steel, pickled	no
Connection type	Screw connector