

Technical data sheet

Washer A2

Item number: 3402320



Washer according to DIN 125, shape A, for universal use.



A2 Stainless steel

2B Bright, treated

Master data

Item number	3402320
Type	WS M10 D20 A2
Description 1	Washer
Manufacturer	OBO
Dimension	M10
Material	Stainless steel
Surface	Bright, treated
Surface standard	
Smallest sales unit	100
Unit of quantity	Piece
Weight	0.408 kg
Weight unit	kg/100 pc.
CO Footprint (GWP) Cradle-to-Gate	0,0174 kg COe / 1 Piece

Dimensions

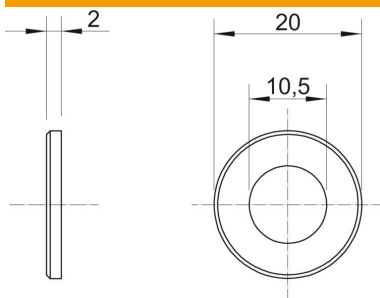


Plate thickness	0.08 in
Dimension D	0.79 in
Dimension d	0.41 in
Dimension d	10.5 mm
Dimension d min.	20 mm
Dimension h	2 mm

Technical data sheet

Washer A2

Item number: 3402320



Technical data

Thread	M10
Inner diameter	10.5 mm
Hole diameter	10.5 mm
Material thickness	2 mm
With toothing	no
Hole shape	Round