

Technical data sheet

Washer A2

Item number: 3402339



Washer according to DIN 125, shape A, for universal use.



A2 Stainless steel

2B Bright, treated

Master data

Item number	3402339
Type	WS M12 D24 A2
Description 1	Washer
Manufacturer	OBO
Dimension	M12
Material	Stainless steel
Surface	Bright, treated
Surface standard	
Smallest sales unit	100
Unit of quantity	Piece
Weight	0.627 kg
Weight unit	kg/100 pc.
CO Footprint (GWP) Cradle-to-Gate	0,0266 kg COe / 1 Piece

Dimensions

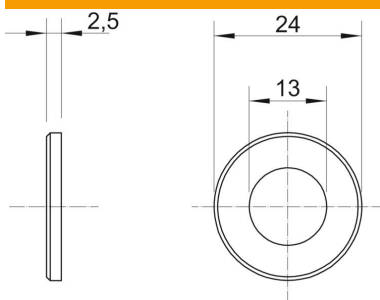


Plate thickness	0.1 in
Dimension D	0.94 in
Dimension d	0.51 in
Dimension d	13 mm
Dimension d min.	24 mm
Dimension h	2.5 mm

Technical data sheet

Washer A2

Item number: 3402339



Technical data

Thread	M12
Inner diameter	13 mm
Hole diameter	13 mm
Material thickness	2.5 mm
With toothing	no
Hole shape	Round