

Technical data sheet

Empty housing X 01

Item number: 2005520



Junction box for the connection of cables and lines indoors and in outdoor areas. Square design without entries. Suitable for wall and ceiling mounting with the option to fasten outside, inside or to mount via the corner domes. Particularly impact resistant with IK09. Transparent cover with quick lock, sealable. Made from halogen-free and UV-resistant materials.

Junction box according to EN 60670. Impact resistance IK09 according to EN 50102. Protection rating IP67 according to EN 60529.



PC Polycarbonate

Master data		
Item number	2005520	
Type	X01C LGR-TR	
Description 1	Empty Enclosure	
Description 2	with transparent lid	
Manufacturer	OBO	
Dimension	95x95x60	
Colour	Grey / transparent	
Material	Polycarbonate	
Smallest sales unit	1	
Unit of quantity	Piece	
Weight	15.6 kg	
Weight unit	kg/100 pc.	
CO Footprint (GWP) Cradle-to-Gate	0,7273 kg COe / 1 Piece	


Technical data sheet

Empty housing X 01


Item number: 2005520



Dimensions

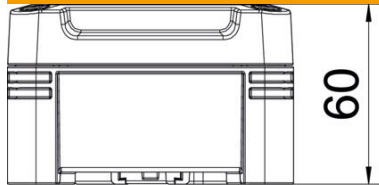

Length	95 mm
Width	95 mm
Height	60 mm

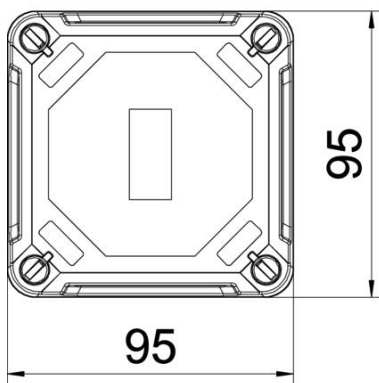

Technical data

Extension option	no
Cover fastening	Screwed
Shape	Square
Suitable for outdoor use	yes
Clear internal dimensions	85x85x45 mm
with lid	yes
Mounting type	Surface-mounted
Protection rating	IP67
Protection rating IK code	IK09
Protection class	II
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C
Transparent lid	yes
Weatherproof	yes