

# Technical data sheet

## Empty housing X 04

Item number: 2005598



Junction box for the connection of cables in indoor and outdoor areas. Square design without entries. Suitable for wall and ceiling mounting with the option to fasten outside, inside or to mount via the corner domes. Particularly impact resistant with IK09. Cover with quick lock, sealable. Made from halogen-free and UV-resistant materials.

Junction box according to DIN EN 60670. Impact resistance IK09 according to DIN EN 50102. Protection rating IP67 according to DIN EN 60529.



PC Polycarbonate

Master data		
Item number	2005598	
Type	X04C SW	
Description 1	Empty Enclosure	
Manufacturer	OBO	
Dimension	114x114x78	
Colour	Graphite black; RAL 9011	
Material	Polycarbonate	
Smallest sales unit	1	
Unit of quantity	Piece	
Weight	26.3 kg	
Weight unit	kg/100 pc.	
CO Footprint (GWP) Cradle-to-Gate	1,0409 kg COe / 1 Piece	


# Technical data sheet

## Empty housing X 04


Item number: 2005598



### Dimensions

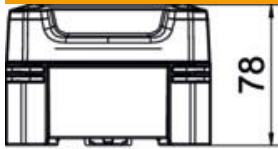

Length	114 mm
Width	114 mm
Height	78 mm

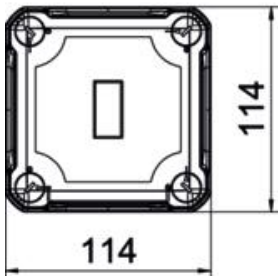

### Technical data

Extension option	no
Cover fastening	Screwed
Shape	Square
Suitable for outdoor use	yes
Clear internal dimensions	102x102x60 mm
with lid	yes
Mounting type	Surface-mounted
Protection rating	IP67
Protection rating IK code	IK09
Protection class	II
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C
Weatherproof	yes