


Technical data sheet

Strain relief on three sides, with mineral wool, internal height 115 mm

Item number: 7215702

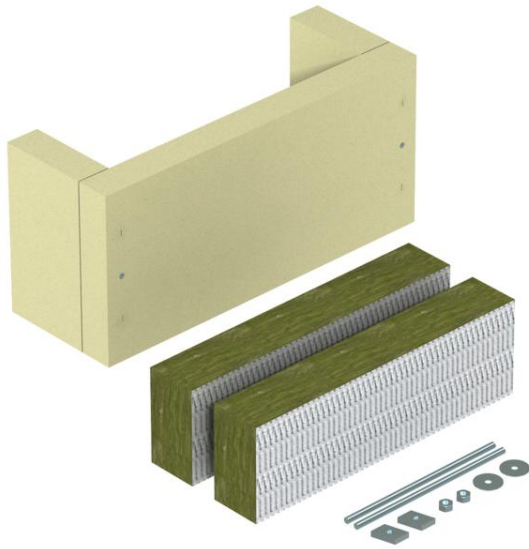

Strain relief as an effective support measure for vertical cable routing, according to DIN 4102 Part 12, approved for all cable types and all vertical routing systems. Maintenance of electrical function classes E30 to E90. Housing including mineral fibre panels, fastening material, ASX fire protection coating in cartridge and identification plate.

Calcium silicate

Master data

| | |
|---------------------|----------------------------|
| Item number | 7215702 |
| Description 1 | Strain relief |
| Description 2 | for vertical cable routing |
| Manufacturer | OBO |
| Dimension | 340x160x140 |
| Colour | Cream; RAL 9001 |
| Material | Calcium silicate |
| Smallest sales unit | 1 |
| Unit of quantity | Piece |
| Weight | 376 kg |
| Weight unit | kg/100 pc. |

Technical data sheet

Strain relief on three sides, with mineral wool, internal height 115 mm
Item number: 7215702



| Dimensions | | |
|------------|-------------|--------|
| | Length | 140 mm |
| | Width | 340 mm |
| | Height | 160 mm |
| | Dimension B | 340 mm |
| | Dimension b | 250 mm |
| | Dimension H | 140 mm |
| | Dimension t | 160 mm |
| | Dimension t | 115 mm |
| | | |

| Technical data | | |
|----------------|-------------------------|-----------------|
| | Fire protection version | Soft insulation |
| | Shape | Rectangular |
| | Accessories required | no |